

## Meet the requirements of the industry

### Realisation of energy savings

- ▶ Using high efficient IE5+ motors and helical bevel gear units

### Reduction of variants by standardisation

- ▶ Using our substantial experience in the dimensioning of gearmotors and inverter, we are able to reduce the number of variants significantly. This leads to a reduction of spare parts

### Plug-and-Play installations


- ▶ Installation and replacement within minutes, using our pluggable system and preset parameters

### Easy maintenance and a global service network

- ▶ NORD DRIVESYSTEMS is based in more than 98 countries with a comprehensive service network. Due to our modular solution, service remains as easy as possible
- ▶ Individual and easy replacement by usage of NORD modular system

### Total Cost of Ownership (TCO)

- ▶ Maint target the reduction of the TCO through the holistic consideration of capital expenditures (CAPEX) and operational costs (OPEX)

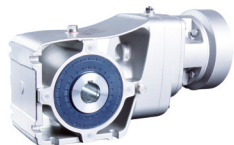

### Helical bevel gear units

- ▶ Highest efficient right-angle gear
- ▶ Space saving
- ▶ Fits best into shape
- ▶ 25% less weight
- ▶ From 50 – 660Nm
- ▶ 0.12 – 9.2 kW
- ▶ Shafts compatible to competitors



### NORD DRIVESYSTEMS Group

- ▶ Family business from Bargteheide near Hamburg with approx. 4,700 employees worldwide
- ▶ Drive solutions for more than 100 branches of industry
- ▶ 7 production locations worldwide
- ▶ Present in 98 countries on 5 continents
- ▶ More information under: [www.nord.com](http://www.nord.com)

EN

Headquarters:  
 Getriebebau NORD GmbH & Co. KG  
 Getriebebau-Nord-Str. 1  
 22941 Bargteheide, Deutschland  
 T: +49 45 32 / 289 0  
 F: +49 45 32 / 289 22 53  
[info@nord.com](mailto:info@nord.com)




Intralogistik solutions  
 for end users


LogiDrive®



- ▶ High efficient 2-stage bevel gear unit
- ▶ IE5+ PMSM synchronous motor
- ▶ Power plug connector
- ▶ Incremental encoder
- ▶ Pre-assembled cables
- ▶ Up to 300% overload capacity possible

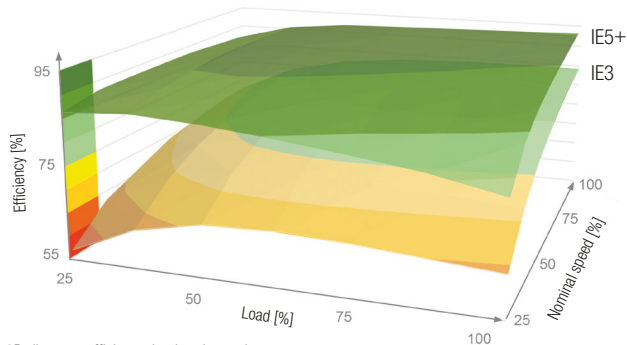

3D diagram: efficiency, load and speed

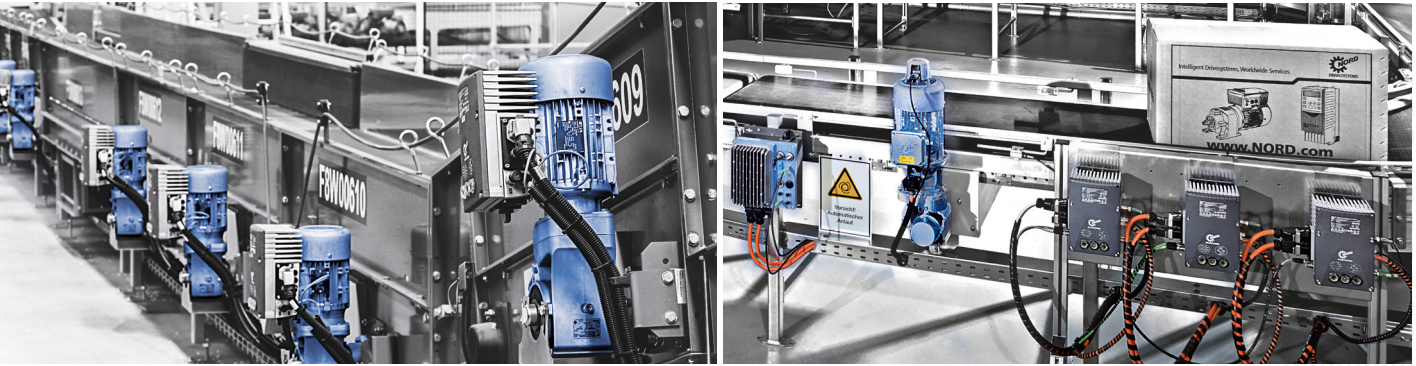

Energy-efficient NORD drive solutions offer great potential for savings in internal conveyor technology and goods handling in trade and industry.

### Realisation of energy savings through super premium efficiency IE5+ synchronous motors

- ▶ Compliant with the most stringent efficiency regulations
- ▶ Considerable TCO reduction

### IE5+ permanent magnet synchronous motors

- ▶ IE5+ synchronous motors make standardisation reasonable and lead to a higher efficient system
- ▶ Even in applications with partial load and partial speed IE5+ motors are high efficient

### NORDAC LINK Field distribution system

- ▶ Pluggable power – less wiring – quick /safe commissioning – daisy chaining
- ▶ Local control with key switch and manual start/stop switch
- ▶ Repair switch for disconnection of mains in service case
- ▶ Pluggable sensors/ actors on-board
- ▶ STO on-board (optional, pluggable)
- ▶ Status indication for device, bus and I/Os
- ▶ Flexible by the selection of needed functions considering the individual need of every customer
- ▶ No extra cabinet needed for switches etc
- ▶ Energy saving functions
- ▶ Integrated braking resistor
- ▶ Ethernet-fieldbus modules
- ▶ Wall mounting

