



 

NORDAC FLEX SK 2x5E

QUICK-START








- (DE)** Dieses Dokument ersetzt nicht die Originalanleitung. Lesen und beachten Sie die Sicherheitshinweise.
- (EN)** This document does not replace the original instructions. Read and observe the safety information.
- (FR)** Ce document ne remplace pas la notice d'origine. Lisez et respectez les consignes de sécurité.
- (ES)** El presente documento no sustituye el manual original. Lea y cumpla las indicaciones de seguridad.
- (SE)** Dokumentet ersätter inte originalbruk-sanvisningen. Läs och följ säkerhetsanvisningarna.
- (NL)** Dit document is geen vervanging voor de originele handleiding. Lees dus de veiligheidsaanwijzingen en volg ze op.
- (PL)** Niniejszy dokument nie zastępuje oryginalnej instrukcji. Przeczytać zasady bezpieczeństwa ostrzegawcze i ich przestrzegać.
- (RU)** Этот документ не является заменой оригинальному руководству. Прочитайте и соблюдайте указания по технике безопасности.
- (CZ)** Tento dokument nenahrazuje originální návod. Přečtěte si a respektujte bezpečnostní upozornění.
- (IT)** Il presente documento non sostituisce le Istruzioni per l'uso originali. Leggere e rispettare le indicazioni di sicurezza.
- (DK)** Dette dokument er ingen erstatning for originalvejledningen. Du bedes læse og følge sikkerhedsanvisningerne.
- (FI)** Tämä asiakirja ei korvaa alkuperäistä käyttöohjetta. Lue turvallisuusohjeet sekä noudata niitä.
- (BR)** Este documento não substitui o manual original. Leia e observe os avisos de segurança.
- (CN)** 这份文档不能替代原版使用说明书。需阅读和注意安全须知和警告提示。
- (TR)** Bu doküman orijinal kılavuzun yerine geçmez. Güvenlik bilgilerini okuyun ve dikkate alın.





NORDAC FLEX SK 2x5E

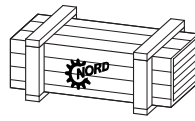


1A

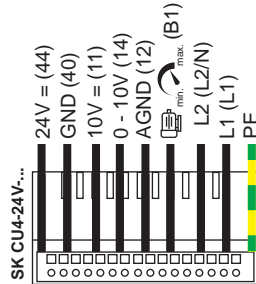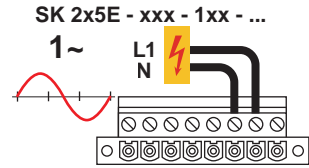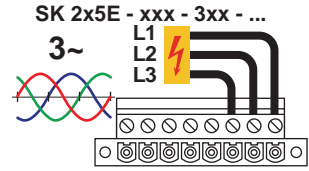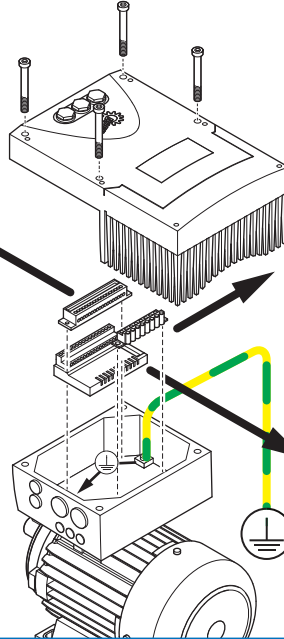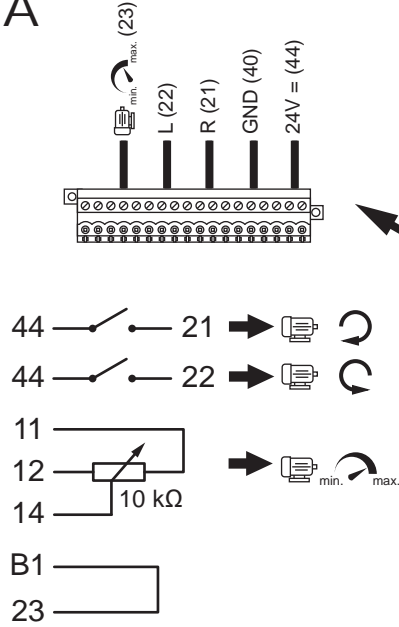

1B

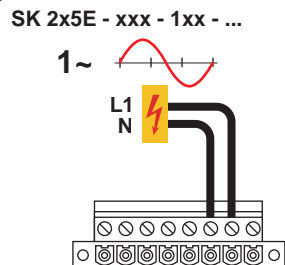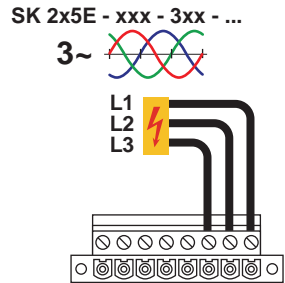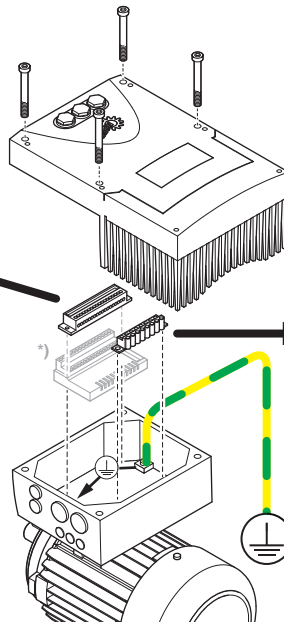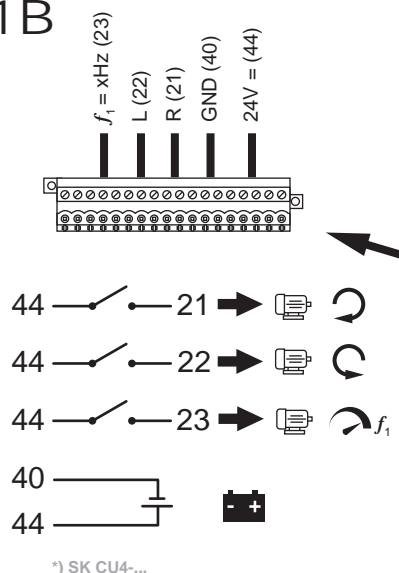


1C

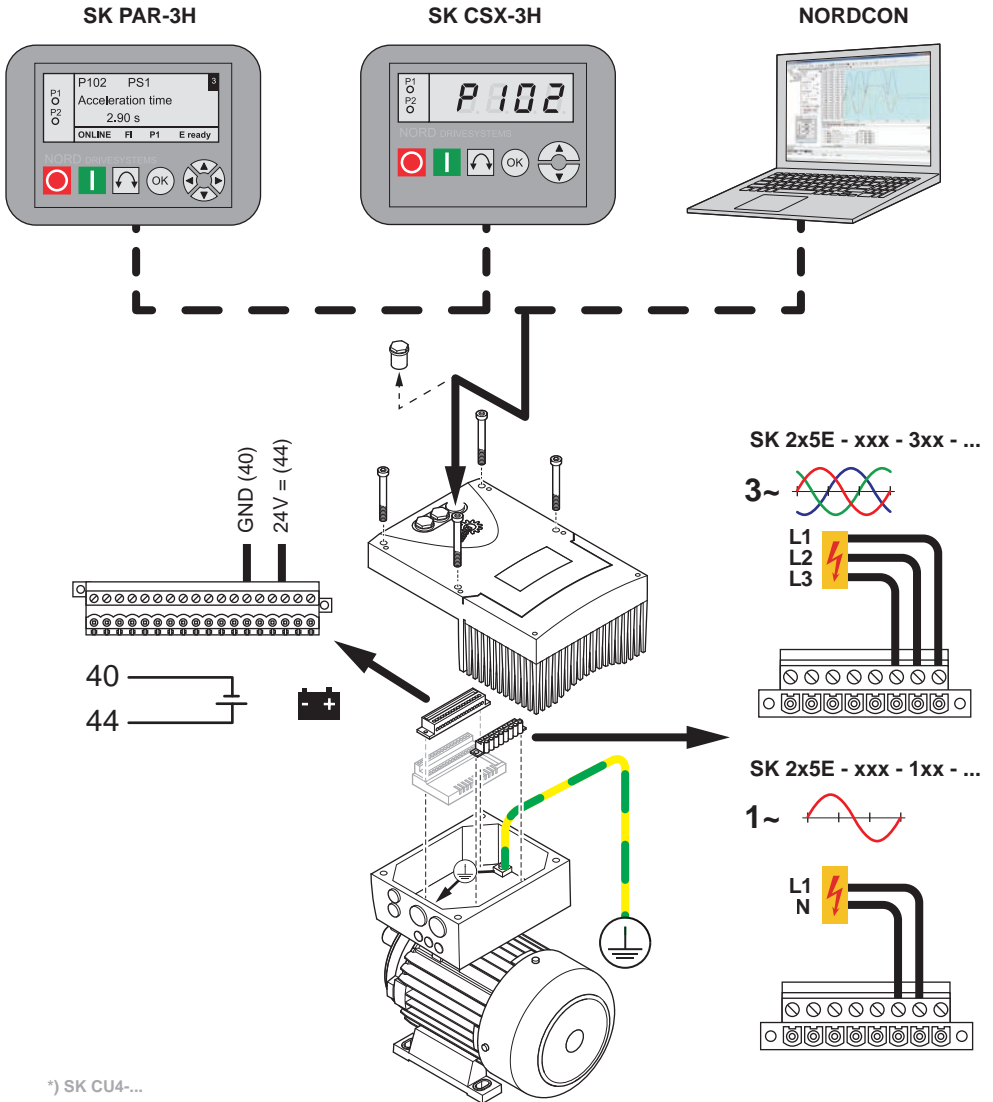


NORDAC FLEX SK 2x5E




SK PAR-3H

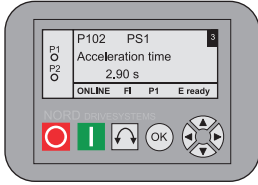

SK CSX-3H

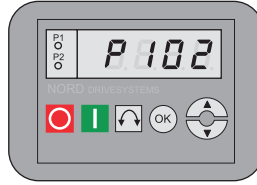

NORDCON

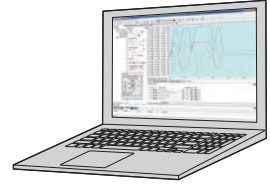

P102		[2.0]	[s]
P103		[2.0]	[s]
P104	f_{\min}	[0.0]	[Hz]
P105	f_{\max}	[50]	[Hz]
P400 [-01]	\rightarrow	[1]	
P420 [-01]		[1]	
P420 [-02]		[2]	
P420 [-03]	$\min.$ $\max.$ f_1	[4]	
P465 [-01]	f_1	[5.0]	[Hz]



www.nord.com

Part No. 6091498 / 4320